


SNSS-FT Hex Socket Head Cap Screws - Full Thread



Full Thread SUS Stainless steel

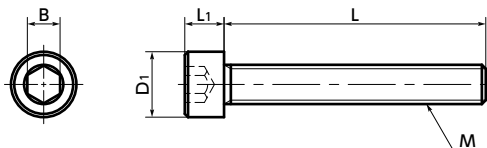

● Full thread socket head cap screws.

● Application

Equipment and devices that require long screws

● Material/Finish



SNSS-FT	
Main Body	SUSXM7 (Equivalent to SUS304)
Strength Class	A2-50

Unit : mm

Part Number	M (Coarse)		L ◀ 2																	D1	L1	B	Mass (g)
	Nominal of Thread ◀ 1	Pitch	25	30	35	40	45	50	55	60	65	70	75	80	85	90	100	110	120				
SNSS-M3-FT	M3	0.5																		5.5	3	2.5	1.6 - 2.9
SNSS-M4-FT	M4	0.7																		7	4	3	3.7 - 11
SNSS-M5-FT	M5	0.8																		8.5	5	4	5.6 - 16
SNSS-M6-FT	M6	1																		10	6	5	9.9 - 24
SNSS-M8-FT	M8	1.25																		13	8	6	21 - 45
SNSS-M10-FT	M10	1.5																		16	10	8	36 - 84

● Part number specification

SNSS - M3 - 25 - FT

Product Code	◀ 1	◀ 2	Product Code
--------------	------------------------------------	------------------------------------	--------------

1 Individual Sales → P.0000	2 Cleanroom Wash & Packaging → P.0000	3 Screw Length Adjustment → P.0000	4 Vibration Resistant → P.0000	5 Modification process for captive use → P.0000
1 piece in 1 pack	Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Not Available