




# SNHP3S Hexagon Head Screws with Captive Washer

Easy operation **SUS** Stainless steel

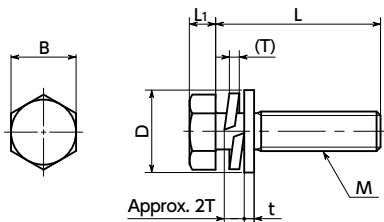

● Material/Finish



	<b>SNHP3S</b>
Screw Body	Equivalent to SUS304
Screw Body Strength Class	A2 - 50
Plain Washer	SUS304
Spring Washer	Equivalent to SUS304

- Hexagon head screws with captive washer compliant with JIS B 1187.
- Old JIS plain washers and spring washers are integrated into the screws, preventing concerns about fallout issues. (Washer abbreviation: P=3)


Unit : mm

Part Number	M (Coarse)		L													D	L1	B	t	T (Approx.)	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch	8	10	12	16	20	25	30	35	40	45	50	26	8							
<b>SNHP3S-M4</b>	M4	0.7	8	10	12	16									10	2.8	7	0.8	1	2 - 2.6	20	
<b>SNHP3S-M5</b>	M5	0.8	8	10	12	16	20	25	30						12	3.5	8	0.8	1.3	3.3 - 6	20	
<b>SNHP3S-M6</b>	M6	1		10	12	16	20	25	30	35					13	4	10	1	1.5	6.5 - 11	20	
<b>SNHP3S-M8</b>	M8	1.25			12	16	20	25	30	35	40	45			18	5.5	13	1.6	2	13 - 24	10	
<b>SNHP3S-M10</b>	M10	1.5					20	25	30	35	40				22	7	17	1.6	2.5	31 - 41	10	
<b>SNHP3S-M12</b>	M12	1.75						20	25	30	35	40	45	50	26	8	19	2.3	3	44 - 66	5	

- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

● Part Number Specification

 **SNHP3S-M8-20**



<b>1</b> Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
Available / Add'l charge	Available / Add'l charge	Not Available	Available / Add'l charge	Not Available