


SNF-SD / SNFS-SD

Cross Recessed Flat Head Machine Screws with Small Head

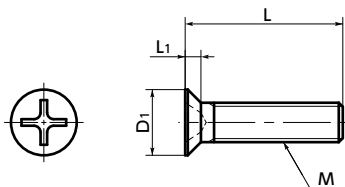

Small Head SUS Stainless steel



- Cross Recessed flat head machine screws with small head diameters. This makes it possible to reduce the spot facing diameters compared to standard flat head machine screws.
- Since the head height is lower than that of standard flat head screws. Suitable for connecting thin plates.

• Application

Reducing the size of equipment and devices

• Material/Finish



	SNF-SD-TZB	SNFS-SD
Main Body	SWCH Trivalent Chromate Treatment	SUSXM7 (Equivalent to SUS304)

SNF-SD-TZB Made of Steel - Trivalent Chromate Treatment

Unit : mm

Part Number	M (Coarse)		L							D1	L1	Cross-recessed Socket Number	Mass (g)	Qty per pack
	Nominal of Thread	Pitch	5	6	8	10	12	16						
SNF-M3-SD-TZB	M3	0.5	5	6	8	10			5	1.3	1	0.41 - 0.61	20	
SNF-M4-SD-TZB	M4	0.7		6	8	10	12	16	6	1.4	2	0.73 - 1.5	20	
SNF-M5-SD-TZB	M5	0.8			8	10	12	16	8	1.9	2	1.7 - 2.7	20	

• When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

SNFS-SD Made of Stainless Steel

Unit : mm

Part Number	M (Coarse)		L							D1	L1	Cross-recessed Socket Number	Mass (g)	Qty per pack
	Nominal of Thread	Pitch	6	8	10	12	16	20	25					
SNFS-M4-SD	M4	0.7	6	8	10	12	16		6	1.4	2	0.73 - 1.5	20	
SNFS-M5-SD	M5	0.8		8	10	12	16	20	8	1.9	2	1.7 - 3.1	20	
SNFS-M6-SD	M6	1			10	12	16	20	10	2.4	3	3.2 - 5.8	20	

• When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

• Part number specification

SNF - M5 - 16 - SD - TZB



Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Not Available