


SNS/SNSS Hex Socket Head Cap Screws for Precision Instruments



Miniature Size SUS Stainless steel

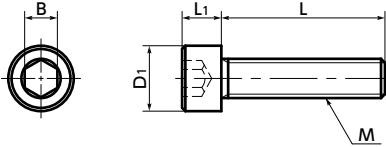

● Material/Finish



	SNS	SNSS
Main Body	SCM435 Ferrosoferric Oxide Film (Black)	SUSXM7 (Equivalent to SUS304)

● M1 - M2.5.

Miniature screws for precision instruments.

● Application

Reducing the size of equipment and devices
Compact precision instruments

SNS Made of Steel · Ferrosoferric Oxide Film

Unit : mm

Part Number	M (Coarse)		L						D1	L1	B	Max. Torque (N·m)	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch	3	4	5	6	8	10						
SNS-M1.6	M1.6	0.35	3	4	5	6			3	1.6	1.5	0.25	0.09 - 0.12	10
SNS-M2	M2	0.4	3	4	5	6			3.8	2	1.5	0.53	0.16 - 0.22	10
SNS-M2-MS	M2	0.4	3		5				3.3	2	1.5	0.53	0.16 - 0.2	10
SNS-M2.5	M2.5	0.45		4	5	6	8		4.5	2.5	2	1.12	0.35 - 0.47	10

● When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

SNSS Made of Stainless Steel


Unit : mm

Part Number	M (Coarse)		L												D1	L1	B	Max. Torque (N·m)	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch	2	3	4	5	6	8	10	12										
SNSS-M1	M1	0.25	2	3	4	5								2	1	0.9	0.02	0.025 - 0.039	10	
SNSS-M1.4	M1.4	0.3	2	3	4	5								2.6	1.4	1.3	0.07	0.062 - 0.085	10	
SNSS-M1.6	M1.6	0.35		3	4	5	6							3	1.6	1.5	0.1	0.09 - 0.12	10	
SNSS-M2	M2	0.4		3	4	5	6	8	10					3.8	2	1.5	0.22	0.16 - 0.3	10	
SNSS-M2.5	M2.5	0.45			4	5	6	8	10	12				4.5	2.5	2	0.46	0.35 - 0.59	10	

● When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

● Usage Example

For fixing miniature linear guideway rails and tables.

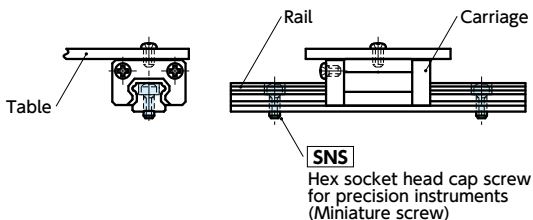

● Part Number Specification



Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
Available / Add'l charge	S.S. only/ Add'l charge	Available / Add'l charge	Available / Add'l charge	Not Available