

● Material/Finish



		<b>NLSPU</b>
Main Body		S25C Ferrosferic Oxide Film (Black)
Hex Socket Head Cap Screw		SCM435 Ferrosferic Oxide Film (Black)
Urethane <b>NSBU</b>	Urethane	Urethane (Black) Shore Hardness A90
	Hex Socket Head Cap Screw with Low Profile	S45C Trivalent Chromate Treatment
	Collar	SUS304


- Compact type stoppers for linear guides with embedded urethane **NSBU**. For space-saving of equipment/devices and applications with limited space.
- Urethane softens the noise of metal hitting metal.
- Hex socket head cap screws for mounting are provided with all products.

● Application

Softens the noise of metal hitting metal  
Table retention and fall prevention  
Stoppers for emergencies

Part Number	Unit : mm														Hex Socket Head Cap Screw	Mass (g)
	W	H	A	B	E	F	G	C	S	P	T	D				
<b>NLSPU-01</b>	14	23	15.5	2	8	10	4	5	16	15	38	5.5	M5×12	55.9		
<b>NLSPU-02</b>	16	27	19.5	2.5	11	12	5	8	19	17	44	6.6	M6×12	87.1		

● Usage Example

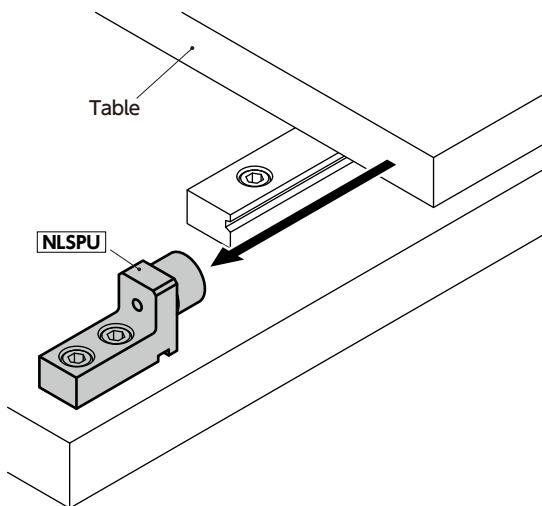

● Related Products

Replacement urethane **NSBU** is available.



● Part Number Specification

**NLSPU-01**



Cleanroom Wash & Packaging	Screw Combination	Screw Length Adjustment	Vibration Resistant	Laser Marking
Not Available	Not Available	Not Available	Not Available	Available / Add'l charge