

● Material/Finish



		NLSPUS
Main Body		SCS13
Hex Socket Head Cap Screw		SUSXM7
Urethane NSBU	Urethane	Urethane (Black) Shore Hardness A90
	Hex Socket Head Cap Screw with Low Profile	S45C Trivalent Chromate Treatment
	Collar	SUS304


- Compact type stoppers for linear guides with embedded urethane **NSBU**. For space-saving of equipment/devices and applications with limited space.
- Urethane softens the noise of metal hitting metal.
- Made of stainless steel. Suitable for environments where corrosion resistance is required.
- Hex socket head cap screws for mounting are provided with all products.
- Application

Softens the noise of metal hitting metal
Table retention and fall prevention
Stoppers for emergencies

Unit : mm

Part Number	W	H	A	B	E	F	G	C	S	P	T	D	Hex Socket Head Cap Screw	Mass (g)
NLSPUS-01	14	23	15.5	2	8	10	4	5	16	15	38	5.5	M5×12	54.3
NLSPUS-02	16	27	19.5	2.5	11	12	5	8	19	17	44	6.6	M6×12	86.8

● Usage Example

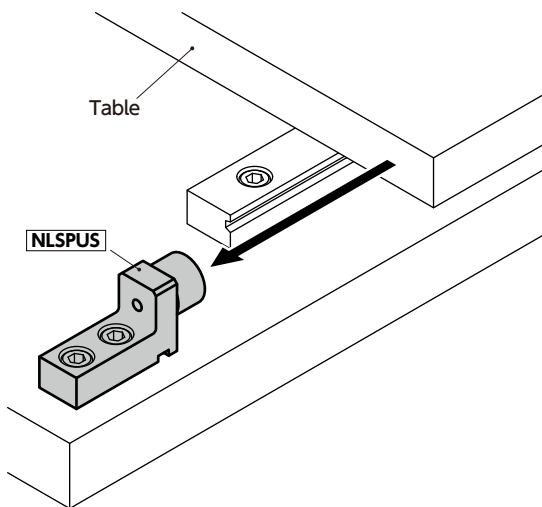

● Related Products

Replacement urethane **NSBU** is available.



● Part Number Specification

NLSPUS-01



Cleanroom Wash & Packaging	Screw Combination	Screw Length Adjustment	Vibration Resistant	Laser Marking
Please feel free to contact us	Not Available	Not Available	Not Available	Available / Add'l charge