



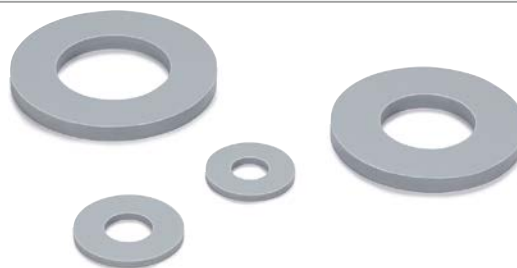

SPPVC-W Plastic Screws - Washer - H - PVC

Chemical-proof

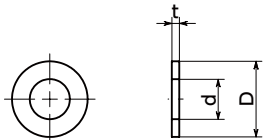

Material/Finish



SPPVC-W	
Main Body	H-PVC (Hard Polyvinyl Chloride) (Gray)
Heat Resistance Temperature*1	60°C

*1 : This is the value for the resin material. The operating temperature of the product changes with performance conditions such as tightening torque.

- Has excellent chemical resistance against organic solvents as well as halogen compounds such as hydrogen sulfide and bromine.
- You can use it even in environments where metal screws cannot be used.
- The properties and precautions of plastic screws
→ P.xxxx
- Application

FPD production equipment / Semiconductor devices / Printed circuit board etching devices / Metallic surface treatment equipment and facilities / Chemical plants

Unit : mm

Part Number	Nominal	d	D	t	Mass (g)
SPPVC-3-W	3	3.2	7	0.5	0.02
SPPVC-4-W	4	4.2	10	1	0.09
SPPVC-5-W	5	5.2	12	1	0.13
SPPVC-6-W	6	6.2	13	1.5	0.22
SPPVC-8-W	8	8.2	18	1.5	0.42
SPPVC-10-W	10	10.5	22	2	0.83
SPPVC-12-W	12	13	24	2	0.91

Part number specification

SPPVC-M5-W



Individual Sales → P.xxxx	Cleanroom Wash & Packaging → P.xxxx	Screw Length Adjustment → P.xxxx	Vibration Resistant → P.xxxx	Modification process for captive use → P.xxxx
1 piece in 1 pack	Available / Add'l charge	Not Available	Not Available	Not Available