


SEQ Cross Recessed Head Cap Screws with Extra Low Profile

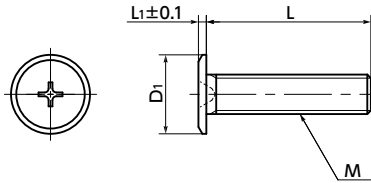

Protrusion



- Cross recessed head cap screws with extra low profile.
- For space-saving of equipment/devices and applications with limited overhead space.
- QuaStix *1 is used for the cross recess. By using a dedicated bit for QuaStix **SKQB**, the torque transmission is improved, preventing cam-out and damage to the cross recess. * 2

* 1 : QuaStix is a registered trademark of OSG Corporation.
 * 2 : It can be mounted and removed with ordinary Phillips bits.

- Select from two surface treatment finish colors.

• Application

Reducing the size of equipment and devices

• Material/Finish



	SEQ-TZB	SEQ-TBZ
Main Body	SWCH Trivalent Chromate Treatment (Silver)	SWCH Black Trivalent Chromate Treatment

 
• Related Products

Dedicated bits for cross recessed head cap screws with extra low profile **SEQ-TZB** **SEQ-TBZ**.



• Part number specification

SEQ-M3-8-TBZ



SEQ-TZB Trivalent Chromate Treatment (Silver) **SEQ-TBZ** Black Trivalent Chromate Treatment

Unit : mm

Part Number ¹	M (Coarse)		L ²				D1	L1	Bit Part No.	Max. Torque (N·m)	Mass (g)	Qty per pack	
	Nominal of Thread	Pitch	6	8	10	12							
SEQ-M3-TZB	M3	0.5	6	8	10	12	7	0.8	SKQB-1	0.7	0.39 - 0.64	50	
SEQ-M4-TZB	M4	0.7		8	10	12	16	8	0.9	SKQB-2	1.8	0.8 - 1.4	50
SEQ-M3-TBZ	M3	0.5	6	8	10	12	7	0.8	SKQB-1	0.7	0.39 - 0.64	50	
SEQ-M4-TBZ	M4	0.7		8	10	12	16	8	0.9	SKQB-2	1.8	0.8 - 1.4	50

• When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

1 Individual Sales	2 Cleanroom Wash & Packaging	3 Screw Length Adjustment	4 Vibration Resistant	5 Modification process for captive use
Available / Add'l charge	Please feel free to contact us	Available / Add'l charge	Available / Add'l charge	Not Available