




SNHS-LH Hex Head Screw / Special Low Profile

Protrusion **SUS** Stainless steel

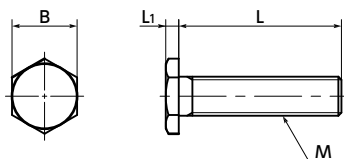

- Hexagon Head Bolt with low head.
- For space-saving of equipment/device and applications with a limited top space.

● Application

Reducing the size of equipment and devices

● Material/Finish



	SNHS-LH
Main body	Equivalent to SUS304

Unit : mm

Part Number	M (Coarse)		L ◀2							L1	B	Mass (g)	Qty per pack
	Nominal of Thread ◀1	Pitch											
SNHS-M4-LH	M4	0.7	8	10	12	15	20	25	30	1.5	7	1.2 - 2.9	10
SNHS-M5-LH	M5	0.8	8	10	12	15	20	25	30	2	8	1.9 - 4.7	10
SNHS-M6-LH	M6	1	10	12	15	20	25	30	2	10	3.2 - 6.9	10	
SNHS-M8-LH	M8	1.25				15	20	25	30	2	13	7.8 - 12	10

● When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

● Part number specification

SNHS - M5 - 25 - LH

Product Code	◀1	◀2	Product Code
--------------	-----------	-----------	--------------

1 Individual Sales → P.0000	2 Cleanroom Wash & Packaging → P.0000	3 Screw Length Adjustment → P.0000	4 Vibration Resistant → P.0000	5 Modification process for captive use → P.0000
Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Available / Add'l charge