


SNBS(INCH) Hex Socket Button Head Cap Screws - Inch Thread

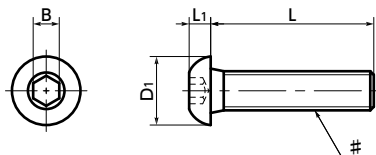

SUS Stainless steel



● Material/Finish



| | |
|----------------|------------------------------|
| | SNBS(INCH) |
| Main Body | Stainless Steel (Grade : A2) |
| Strength Class | A2-50 |

- Socket button head cap screws with inch thread.
- ANSI B18.3 compliance.
- Install and remove by using **SKH(INCH)** Specialty Key. → P.xxxx
- Also, products with special specifications such as dimensions, shapes, materials, surface treatments, cleanroom washing and special packaging are available. → P.xxxx



● Application

Equipment and devices using inch screw specifications

Unit : inch

| Part Number | # | L | | | | | | | | D1 | L1 | B | Mass (g) | Qty per pack | |
|----------------------|-------------------|--------|-------|--------|-------|-------|-------|-------|-------|-------|-------|--------|-------------|--------------|----|
| | Nominal of Thread | | | | | | | | | | | | | | |
| SNBS-#4-40 | No.4-40UNC | 3 / 16 | 1 / 4 | 5 / 16 | 3 / 8 | 1 / 2 | | | | 0.213 | 0.059 | 1 / 16 | 0.35 - 0.65 | 10 | |
| SNBS-#5-40 | No.5-40UNC | | 1 / 4 | | 3 / 8 | 1 / 2 | | | | 0.238 | 0.066 | 5 / 64 | 0.53 - 0.85 | 10 | |
| SNBS-#6-32 | No.6-32UNC | | 1 / 4 | 5 / 16 | 3 / 8 | 1 / 2 | 5 / 8 | 3 / 4 | | 0.262 | 0.073 | 5 / 64 | 0.67 - 1.4 | 10 | |
| SNBS-#8-32 | No.8-32UNC | | 1 / 4 | | 3 / 8 | 1 / 2 | 5 / 8 | 3 / 4 | | 0.312 | 0.087 | 3 / 32 | 1.1 - 2.1 | 10 | |
| SNBS-#10-24 | No.10-24UNC | | 1 / 4 | | 3 / 8 | 1 / 2 | 5 / 8 | 3 / 4 | 7 / 8 | 1 | 0.361 | 0.101 | 1 / 8 | 1.5 - 3.6 | 10 |
| SNBS-#10-32 | No.10-32UNF | | 1 / 4 | | 3 / 8 | 1 / 2 | 5 / 8 | 3 / 4 | 7 / 8 | 1 | 0.361 | 0.101 | 1 / 8 | 1.5 - 3.8 | 10 |
| SNBS-1 / 4-20 | 1/4-20UNC | | | | 3 / 8 | 1 / 2 | 5 / 8 | 3 / 4 | 7 / 8 | 1 | 0.437 | 0.132 | 5 / 32 | 3.3 - 6.4 | 10 |

- All dimensions are in inches.
- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

● Part number specification

SNBS-#4-40-1/4



| | | | | |
|-------------------------------------|---|--|--|---|
| 1 Individual Sales → P.xxxxx | 2 Cleanroom Wash & Packaging → P.xxxxx | 3 Screw Length Adjustment → P.xxxxx | 4 Vibration Resistant → P.xxxxx | 5 Modification process for captive use → P.xxxxx |
| Available / Add'l charge | Available / Add'l charge | Available / Add'l charge | Available / Add'l charge | Available / Add'l charge |