

- For locating work.
- Pin materials can be selected by a product code.
 - PST** — Steel pin
 - PSTS** — Stainless steel pin
 - PST-N** — Plastic pin


● Material/Finish



	PST	PSTS	PST-N
Main body	Equivalent to SUS303	Equivalent to SUS303	Equivalent to SUS303
Pin	S45C (hardness: 40 - 45 HRC) Ferrosferric Oxide Film (Black)	SUS440C (hardness: 55 - 60 HRC)	Polyacetal (hardness: 94 HRM)
Spring	SUS631J1	SUS631J1	SUS631J1

Part Number	PST	Steel Pin	PSTS	Stainless Steel Pin	PST-N	Plastic Pin												Unit : mm	
	D	s	L	L1	d	H	H1	h	W	e	A	t	P	C	R	Load (N) min./max.	Mass (g)		
PST-10	10	2.5	20	6	5.5	10.5	5.5	4.8	23	3	6.5	0.5	17	6	3.4	25 / 43	60		
PST-15	15	4.5	26	9	7	15.5	8	6	34	4	11	1	25	8	4.5	39 / 84	70		
PST-20	20	6	35	13	8.5	21	11	7	47	5	13.5	1	34	11	6.6	32 / 161	180		
PST-10-N	10	2.5	20	6	5.5	10.5	5.5	4.8	23	3	6.5	0.5	17	6	3.4	25 / 43	60		
PST-15-N	15	4.5	26	9	7	15.5	8	6	34	4	11	1	25	8	4.5	39 / 84	70		
PST-20-N	20	6	35	13	8.5	21	11	7	47	5	13.5	1	34	11	6.6	32 / 161	180		
PSTS-10	10	2.5	20	6	5.5	10.5	5.5	4.8	23	3	6.5	0.5	17	6	3.4	25 / 43	60		
PSTS-15	15	4.5	26	9	7	15.5	8	6	34	4	11	1	25	8	4.5	39 / 84	70		
PSTS-20	20	6	35	13	8.5	21	11	7	47	5	13.5	1	34	11	6.6	32 / 161	180		

● Usage example

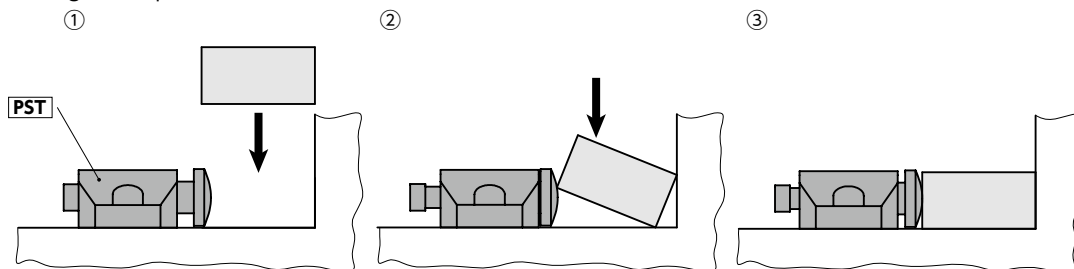

● Part number specification

PST-10-N
1 2 1

Cleanroom Wash & Packaging → P.xxxx	Vibration Resistant → P.xxxx	Laser Marking → P.xxxx
Please feel free to contact us	Not Available	Not Available