




SNFC Hexagon Socket Countersunk Head Screws



● Material/Finish

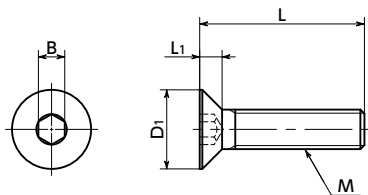

	SNFC
Main Body	SCM435 Ferrosferric Oxide Film (Black)
Strength Class	10.9

- Hex socket countersunk head screws conforming to SSS Standard.

Unit : mm

Part Number ◀1	M (Coarse)		L ◀2										D1	L1	B	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch	5	6	8	10	12	16	20								
SNFC-M3	M3	0.5	5	6	8	10	12	16	20				6	1.7	2	0.35 - 0.94	20
SNFC-M4	M4	0.7	6	8	10	12	16	20	25	30		8	2.3	2.5	0.85 - 2.5	20	
SNFC-M5	M5	0.8		8	10	12	16	20	25	30	35	10	2.8	3	1.7 - 4.7	20	

- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

● Part Number Specification

SNFC-M3-8



Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
Available / Add'l charge	Not Available	Available / Add'l charge	Available / Add'l charge	Not Available