


SSHS-UCL Hex Socket Head Cap Screws with Special Low Profile (SUSXM7 / Cleanroom Washing/Cleanroom Packing)



Protrusion
 Cleanroom wash & packaging
 SUS Stainless steel

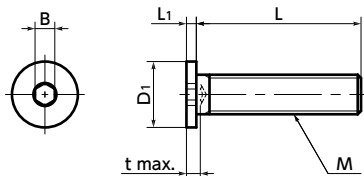

● Material/Finish



SSHS-UCL	
Main Body	SUSXM7 (Equivalent to SUS304) USC Cleaning
Strength Class	A2 - 50



- SUSXM7 hex socket head cap screw with special low profile.
- All head heights are 1.5 mm or less. For space-saving of equipment/devices and applications with limited overhead space.
- Cleanroom wash/cleanroom packing provided.
- For parts embedded in FPD production devices, semiconductor manufacturing devices, medical equipment, or food machinery, or used in cleanrooms.
- SUS316L **SSHL-UCL** is available.

SSHL-UCL **SSHS-UCL**



To distinguish it from **SSHS-UCL**, **SSHL-UCL** has a cup point tip.

● Application

Reducing the size of equipment and devices
 FPD manufacturing equipment / Semiconductor manufacturing equipment /
 Medical equipment / Food related machinery

Unit : mm

Part Number 1	M (Coarse)		L 2												D1	L1	B	t max.	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch																		
SSHS-M2-UCL	M2	0.4	4	5	6	8	10	12							4	1.1	1.3	1.2	0.11 - 0.29	10
SSHS-M2.5-UCL	M2.5	0.45	4	5	6	8	10	12							5	1.3	1.3	1.5	0.23 - 0.47	10
SSHS-M3-UCL	M3	0.5	4	5	6	8	10	12							6	1.3	1.5	2	0.36 - 0.69	10
SSHS-M4-UCL	M4	0.7			6	8	10	12	16						8	1.5	2	2.5	0.89 - 1.6	10
SSHS-M5-UCL	M5	0.8			6	8	10	12	16	20	25				9	1.5	3	3	0.73 - 3.3	10
SSHS-M6-UCL	M6	1			6	8	10	12	16	20	25	30			10	1.5	3	4	1.2 - 5.5	10

● When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

● Part Number Specification

SSHS-M5-12-UCL



Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
Available / Add'l charge	Cleanroom washed and packed	Available / Add'l charge	Not Available	Not Available